


# Suction cup with connection ESS-40-BU

Part number: 189387

FESTO

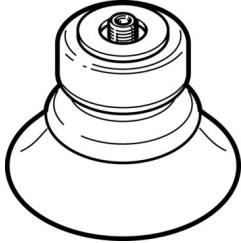

 [General operating condition](#)

## Data sheet

Feature	Value
Height compensator for suction cup	9.5 mm
Min. workpiece radius	90 mm
Nominal size	3 mm
Suction cup diameter	40 mm
Suction cup volume	8.87 cm <sup>3</sup>
Position of connection	Top
Mounting position	optional
Symbol	00991485
Correlation to suction-cup holder	Size 4
Suction cup shape	Round bellows 1.5 convolutions
Operating pressure	-0.095 MPa ... 0 MPa
Operating pressure	-0.95 bar ... 0 bar
Operating pressure	-13.775 psi ... 0 psi
Nominal operating pressure	-0.07 MPa
Nominal operating pressure	-0.7 bar
Nominal operating pressure	-10.15 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Suitable for use with food	See supplementary material information
Ambient temperature	-20 °C ... 60 °C
Holding force at nominal operating pressure	52.3 N
Lateral force at nominal operating pressure	33 N
Product weight	18.7 g
Type of mounting	Via vacuum port
Vacuum connection	M6
Colour	Blue
Shore hardness	60 +/- 5
Material screwed plug	Nickel-plated wrought aluminium alloy Nickel-plated brass Steel, galvanised and chrome-plated

Feature	Value
Note on materials	RoHS-compliant
Material suction cup	PUR