



Suction cup with connection ESS-20X60-ON

Part number: 189416

FESTO

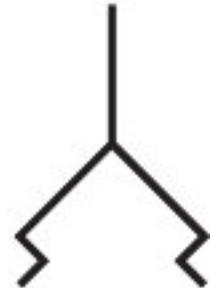

 [General operating condition](#)

Data sheet

Feature	Value
Nominal size	6 mm
Suction cup size	20x60 mm
Suction cup volume	3.69 cm ³
Position of connection	Top
Mounting position	optional
Symbol	00991485
Correlation to suction-cup holder	Size 5
Suction cup shape	Oval, flat
Operating pressure	-0.095 MPa ... 0 MPa
Operating pressure	-0.95 bar ... 0 bar
Operating pressure	-13.775 psi ... 0 psi
Nominal operating pressure	-0.07 MPa
Nominal operating pressure	-0.7 bar
Nominal operating pressure	-10.15 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-A1-L
Suitable for use with food	See supplementary material information
Ambient temperature	-10 °C ... 70 °C
Holding force at nominal operating pressure	62.8 N
Horizontal lateral force at nominal operating pressure	116 N
Vertical lateral force at nominal operatin pressure	63 N
Product weight	30.8 g
Type of mounting	Via vacuum port
Vacuum connection	M10
Colour	Black
Shore hardness	50 +/- 5
Note on materials	RoHS-compliant
Material suction cup	NBR