


Suction cup without connector ESV-30-CS

Part number: 191074

FESTO

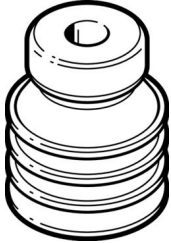

[PDF](#) General operating condition

Data sheet

Feature	Value
Height compensator for suction cup	10.5 mm
Min. workpiece radius	80 mm
Suction cup diameter	30 mm
Suction cup volume	9.47 cm ³
Position of connection	Top
Mounting position	optional
Symbol	00991485
Suction cup shape	Round bellows 3.5 convolutions
Operating pressure	-0.095 MPa ... 0 MPa
Operating pressure	-0.95 bar ... 0 bar
Operating pressure	-13.775 psi ... 0 psi
Nominal operating pressure	-0.07 MPa
Nominal operating pressure	-0.7 bar
Nominal operating pressure	-10.15 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
LABS (PWIS) conformity	VDMA24364 zone III
Suitable for use with food	See supplementary material information
Ambient temperature	-30 °C ... 180 °C
Holding force at nominal operating pressure	20.8 N
Product weight	5.8 g
Colour	Transparent
Shore hardness	50 +/- 5
Note on materials	RoHS-compliant
Material suction cup	VMQ (silicone)