


Interface CAMC-F-PN

Part number: 1911916

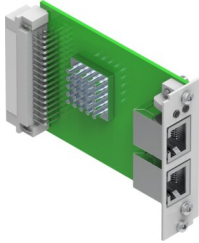

 [General operating condition](#)

Data sheet

Feature	Value
Dimensions (W x L x H)	19 x 90 x 65 mm
CE mark (see declaration of conformity)	To EU EMC Directive
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C ... 70 °C
Relative air humidity	5 - 95% Non-condensing
Degree of protection	IP20 In assembled state
Ambient temperature	0 °C ... 50 °C
Product weight	75 g
Type of mounting	Plug-in module for CMMP-AS...-M3
Note on materials	RoHS-compliant
Mounting position	optional
Protocol	PROFINET
Communication profile	FHPP
Baud rate	10/100 Mbit/s (full/half)
Topologies	Star Ring Line
Media redundancy	MRP
IP address allocation	FCT DCP
Field bus interface	2x RJ45 socket
Min. cycle time	1 ms
LED display	Bus fault Ethernet communication activity Ethernet line monitoring System fault
Configuration support	GSDML
Parameterisation	FCT
Additional functions	IRT-compatible LLDP MRP PROFenergy Real-time class 1 SNMP