


# Vacuum filter ESF-3

Part number: 191202

FESTO

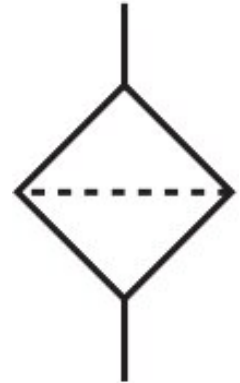

 [General operating condition](#)

## Data sheet

Feature	Value
Mounting position	optional
Grade of filtration	10 µm
Symbol	00991483
Operating pressure	-0.95 bar ... 4 bar
Flow rate with vacuum = -0.075 MPa (-0.75 bar, -10.875 psi)	100 l/min
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-A1-L
Ambient temperature	0 °C ... 60 °C
Product weight	9 g
Type of mounting	Via male thread Via vacuum port
Pneumatic connection	M4
Vacuum connection	M4
Note on materials	RoHS-compliant
Material seals	NBR
Material filter	PVF
Material housing	Aluminium Brass, nickel-plated