


# Manifold block MHP1-PR6-3-PI

Part number: 197214

FESTO

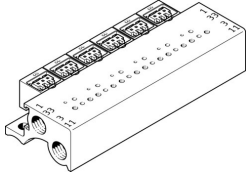

 [General operating condition](#)

## Data sheet

| Feature                            | Value  |
|------------------------------------|--|
| Max. number of valve positions     | 6  |
| Operating pressure                 | 0 bar ... 8 bar  |
| Operating medium                   | Compressed air to ISO 8573-1:2010 [7:4:4]  |
| Note on operating and pilot medium | Lubricated operation possible (in which case lubricated operation will always be required) |
| Corrosion resistance class CRC     | 1 - Low corrosion stress   |
| LABS (PWIS) conformity             | VDMA24364-B2-L   |
| Ambient temperature                | -10 °C ... 60 °C   |
| Mounting method for sub-base       | With through-hole  |
| Mounting method for valve          | Via female thread  |
| Pneumatic connection, port 1       | M7   |
| Pneumatic connection, port 3       | M7   |
| Material sub-base                  | Wrought aluminium alloy  |