


# Distributor block FR-8-1/8

Part number: 2077

FESTO

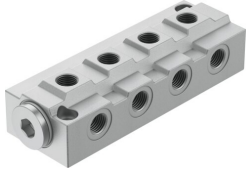

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal size	8.6 mm
Mounting position	optional
Operating pressure complete temperature range	0 bar ... 16 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Nominal torque	12.5 Nm
Tolerance for nominal tightening torque	± 20%
Product weight	135 g
Number of outputs	8
Number of supply lines	1
Pneumatic connection, port 1	Female thread G3/8
Pneumatic connection, port 2	Female thread G1/8
Note on materials	RoHS-compliant
Material housing	Die-cast aluminium