


# Distributor block FR-8-1/4

Part number: 2078

FESTO

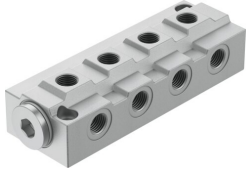

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal size	11.5 mm
Mounting position	optional
Operating pressure complete temperature range	0 bar ... 16 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Nominal torque	14 Nm
Tolerance for nominal tightening torque	± 20%
Product weight	230 g
Number of outputs	8
Number of supply lines	1
Pneumatic connection, port 1	Female thread G1/2
Pneumatic connection, port 2	Female thread G1/4
Note on materials	RoHS-compliant
Material housing	Die-cast aluminium