


# Sub-base VABP-S3-26V1G-G18-2M-R3

Part number: 2605075

FESTO

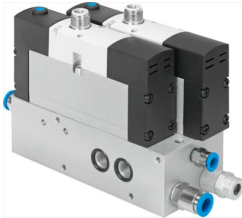

 [General operating condition](#)

## Data sheet

Feature	Value
Construction width	26 mm
Function port 32	G1/8
Function port 34	G1/8
Pneumatic port 22	Sub-base G1/8
Pneumatic port 44	Sub-base G1/8
Mounting position	optional
Operating pressure	0 bar ... 16 bar
Pilot pressure	3 bar ... 8 bar
Standard nominal flow rate (standardised to DIN 1343)	800 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [6:4:4]
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	0 °C ... 50 °C
Ambient temperature	0 °C ... 50 °C
Product weight	1200 g
Pilot air port 14	M5
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 4	G1/8
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy
Material o-ring	NBR
Material screws	Steel