


Parallel kit EAMM-U-110-D50-100A-120-S1

Part number: 2799488

FESTO

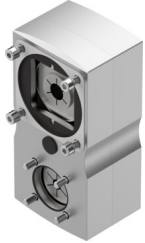

 [General operating condition](#)

Data sheet

| Feature | Value |
|---------------------------------------|-----------------------|
| Size | 110 |
| Mounting position | optional |
| Gear unit ratio | 1:1 |
| Max. rotational speed | 5000 rpm |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95% |
| Degree of protection | IP65 |
| Ambient temperature | -10 °C ... 60 °C |
| Mass moment of inertia | 799 kgmm ² |
| Frictional torque independent of load | 0.3 Nm |
| Transmittable torque | 25 Nm |
| Product weight | 5050 g |
| Interface code, actuator | D50B |
| Interface code, motor in | 100A |
| Note on materials | RoHS-compliant |