


# Flange mounting EAHH-V2-40-R1

Part number: 2827588

FESTO

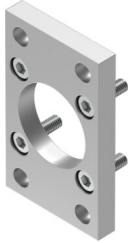

 [General operating condition](#)

## Data sheet

| Feature   | Value  |
|---|--|
| Size  | 40   |
| Based on standard   | ISO 15552  |
| Corrosion resistance class CRC                            | 3 - high corrosion stress  |
| LABS (PWIS) conformity                                    | VDMA24364-B2-L   |
| Suitability for the production of Li-ion batteries        | Suitable for battery production with reduced Cu/Zn/Ni values (F1a)                       |
| Cleanroom suitability, measured according to ISO 14644-14 | Element installed statically, no meaningful evaluation possible according to ISO 14644-1 |
| Max. load capacity  | 3 kN   |
| Product weight  | 275 g  |
| Note on materials   | RoHS-compliant   |
| Material plate  | High-alloy stainless steel   |
| Material screws   | High-alloy stainless steel   |