


Swivel flange CRSNCS-63

Part number: 2895923

FESTO

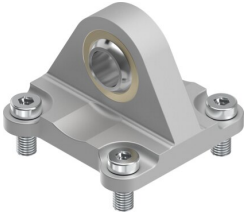

 [General operating condition](#)

Data sheet

| Feature | Value |
|--|--|
| Size | 63 |
| Based on standard | ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290) |
| Variants | High corrosion protection |
| Corrosion resistance class CRC | 4 - Very high corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Suitability for the production of Li-ion batteries | Metals with more than 5% by mass of copper, zinc or nickel are excluded from use. Exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils. |
| Ambient temperature | -40 °C ... 150 °C |
| Max. load capacity | 4 kN |
| Product weight | 576 g |
| Note on materials | RoHS-compliant |
| Material mounting | High-alloy stainless steel |
| Material rod end bearing | PTFE Stainless steel |
| Material screws | High-alloy stainless steel |