


Axial kit EAMM-A-D32-60G-S1

Part number: 2946759

FESTO

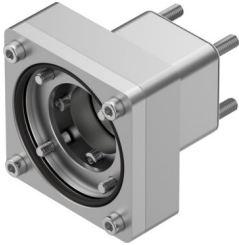

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------|------------------------|
| Nominal length | 67.5 mm |
| Mounting position | optional |
| Max. rotational speed | 8000 rpm |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95% |
| Degree of protection | IP65 |
| Ambient temperature | -10 °C ... 60 °C |
| Mass moment of inertia | 5.87 kgmm ² |
| Transmittable torque | 6.5 Nm |
| Product weight | 540 g |
| Interface code, actuator | D32 |
| Interface code, motor in | 60G |
| Note on materials | RoHS-compliant |