


Plug socket with cable KMF-1-230AC-5

Part number: 30938

FESTO

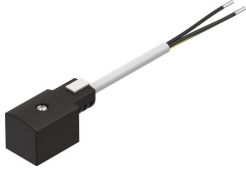

 [General operating condition](#)

Data sheet

| Feature | Value |
|--|---|
| Type of mounting | On solenoid valve via M3 central screw |
| Mounting position | optional |
| Product weight | 320 g |
| Electrical connection | Socket |
| Nominal operating voltage AC | 230 V |
| Protective conductor connection | Available |
| Cable length | 5 m |
| Cable diameter | 6 mm |
| Cable structure | 3 x 0.75 mm ² |
| Degree of protection | IP67 To IEC 60529 |
| Ambient temperature | -20 °C ... 80 °C |
| CE mark (see declaration of conformity) | To EU Low Voltage Directive In accordance with EU RoHS Directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions To UK regulations for electrical equipment |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Material cable sheath | PVC |
| Material housing | PC POM |
| Material electrical contact | Bronze |