


# Plug socket with cable KMV-1-24DC-5-LED

Part number: 30941

FESTO

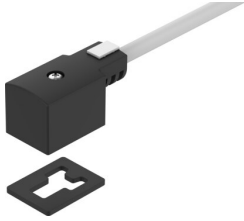

 [General operating condition](#)

## Data sheet

Feature	Value
Switching status indication	LED
Type of mounting	On solenoid valve via M3 central screw
Mounting position	optional
Product weight	320 g
Electrical connection	Socket Type B
Nominal operating voltage DC	24 V
Reverse polarity protection	For all electrical connections
Protective conductor connection	Available
Cable length	5 m
Cable diameter	6 mm
Cable structure	3 x 0.75 mm <sup>2</sup>
Degree of protection	IP67 To IEC 60529
Ambient temperature	-20 °C ... 80 °C
CE mark (see declaration of conformity)	In accordance with EU RoHS Directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
LABS (PWIS) conformity	VDMA24364-B2-L
Corrosion resistance class CRC	1 - Low corrosion stress
Material cable sheath	PVC
Material housing	PC
Material electrical contact	Bronze