


# Axial kit EAMM-A-D100-100A

Part number: 3356796

FESTO

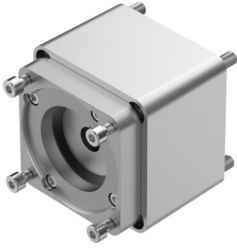

 [General operating condition](#)

## Data sheet

| Feature                  | Value                 |
|--------------------------|-----------------------|
| Nominal length           | 99.5 mm               |
| Mounting position        | optional              |
| Max. rotational speed    | 5500 rpm              |
| LABS (PWIS) conformity   | VDMA24364-B2-L        |
| Storage temperature      | -25 °C ... 60 °C      |
| Relative air humidity    | 0 - 95%               |
| Degree of protection     | IP40                  |
| Ambient temperature      | -10 °C ... 60 °C      |
| Mass moment of inertia   | 128 kgmm <sup>2</sup> |
| Transmittable torque     | 60 Nm                 |
| Product weight           | 2450 g                |
| Interface code, actuator | D100                  |
| Interface code, motor in | 100A                  |
| Note on materials        | RoHS-compliant        |