


# Axial kit EAMM-A-S48-57A-G2

Part number: 3637963

FESTO

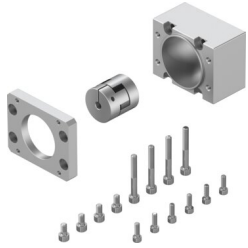

## Data sheet

 [General operating condition](#)

Feature	Value
Nominal length	47.2 mm
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	5.87 kgmm <sup>2</sup>
Transmittable torque	6.5 Nm
Product weight	570 g
Interface code, actuator	S48
Interface code, motor in	57A
Note on materials	RoHS-compliant