


Axial kit EAMM-A-T42-60P

Part number: 4133487

FESTO

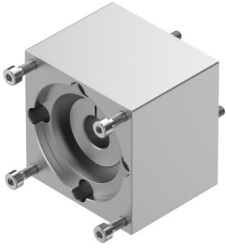

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------|-----------------------|
| Nominal length | 49 mm |
| Mounting position | optional |
| Max. rotational speed | 8000 rpm |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95% |
| Degree of protection | IP40 |
| Ambient temperature | -10 °C ... 60 °C |
| Mass moment of inertia | 3.2 kgmm ² |
| Transmittable torque | 10 Nm |
| Product weight | 334 g |
| Interface code, actuator | T42 |
| Interface code, motor in | 60P 60PA |
| Note on materials | RoHS-compliant |