


Axial kit EAMM-A-V20-28A

Part number: 4505258

FESTO

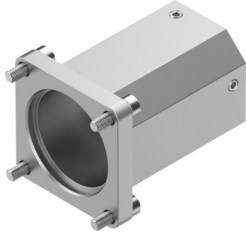

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	36.4 mm
Mounting position	optional
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	0.022 kgmm ²
Transmittable torque	0.2 Nm
Product weight	27 g
Interface code, actuator	V20
Interface code, motor in	28A
Note on materials	RoHS-compliant