


Axial kit EAMM-A-T46-80P

Part number: 4624170

FESTO

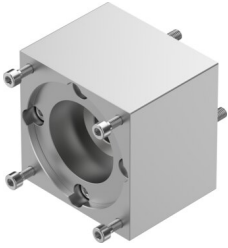

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	63.1 mm
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	3.2 kgmm ²
Transmittable torque	10 Nm
Product weight	840 g
Interface code, actuator	T46
Interface code, motor in	80P
Note on materials	RoHS-compliant