


# Manifold MHA2-PR10-5-M5

Part number: 525131

FESTO

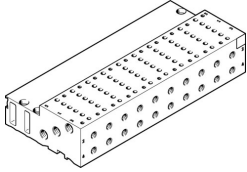

 [General operating condition](#)

## Data sheet

Feature	Value
Max. number of valve positions	10
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	597 g
Mounting method for sub-base	With through-hole With H-rail
Mounting method for valve	Via female thread
Pneumatic connection, port 1	M7
Pneumatic connection, port 2	M5
Pneumatic connection, port 3	M7
Pneumatic connection, port 4	M5
Pneumatic connection, port 5	M7
Material sub-base	Wrought aluminium alloy