


Push-in L-fitting QBML-10-32-UNF-1/8-U

Part number: 533285

FESTO

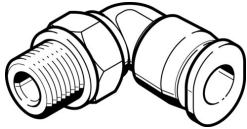

 General operating condition

Data sheet

Feature	Value
Size	Standard
Nominal size	2.489 mm
Type of seal on screwed plug	Sealing ring
Mounting position	optional
Design	L-shape
Size of pack	10
Design	Push-pull principle
Operating pressure complete temperature range	-0.095 MPa ... 1 MPa
Operating pressure complete temperature range	-0.95 bar ... 10 bar
Operating pressure complete temperature range	-13.775 psi ... 145 psi
Operating medium	Compressed air to ISO 8573-1:2010 [7::-:]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	0 °C ... 60 °C
Max. tightening torque	1.5 Nm
Product weight	4.394 g
Type of mounting	External hex 5/16
Pneumatic connection, port 1	Male thread 10-32 UNF-2A
Pneumatic connection, port 2	For tubing O.D. 1/8"
Ambient temperature	32 °F ... 140 °F
Colour of release ring	grey
Note on materials	RoHS-compliant
Material housing	PBT
Material release ring	POM
Material tubing seal	NBR
Material tubing clamp component	High-alloy stainless steel