


# Connecting cable NEBV-S1G25-K-10-N-LE15

Part number: 538224

FESTO

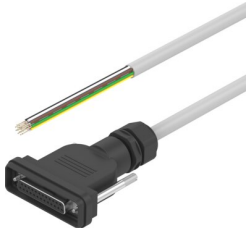

 [General operating condition](#)

## Data sheet

Feature	Value
Type of mounting	4-40 UNC-2B
Product weight	1270 g
Electrical connection 1	Sub-D socket, 25-pin
Electrical connection 2	Open end, 15-wire
Nominal operating voltage DC	24 V
Cable length	10 m
Cable characteristic	Standard
Min. cable bending radius	90 mm
Cable diameter	9 mm
Cable structure	15 x 0.34 mm <sup>2</sup>
Degree of protection	IP65 IP67 In assembled state
Ambient temperature with moving cable	-5 °C ... 50 °C
CE mark (see declaration of conformity)	In accordance with EU RoHS Directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class CRC	2 - Moderate corrosion stress
Material cable sheath	PVC
Material housing	PBT
Material union nut	PA
Material seals	TPE-O