
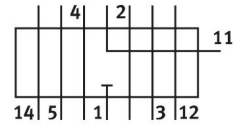


Vertical pressure supply plate

VABF-S4-1-P1A3-N14

FESTO

Part number: 540172

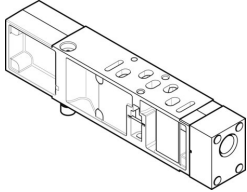

 General operating condition

Data sheet

Feature	Value
Construction width	26 mm
Based on standard	ISO 15407-2
Mounting position	Any
Symbol	00991883
Operating pressure	1 MPa
Operating pressure	10 bar
CE mark (see declaration of conformity)	To EU Low Voltage Directive
UKCA marking (see declaration of conformity)	To UK regulations for electrical equipment
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 NEMA 4
Pilot medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Ambient temperature	-5 °C ... 50 °C
Product weight	191 g
Mounting with vertical stacking	On manifold sub-base On individual sub-base
Pneumatic connection, port 1	1/4 NPT
Material housing	Die-cast aluminium