 



Throttle plate VABF-S4-2-F1B1-C

Part number: 540176

FESTO

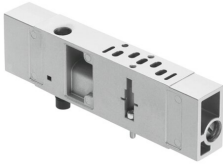

[PDF](#) [General operating condition](#)

Data sheet

| Feature | Value |
|--|--|
| Construction width | 18 mm |
| Based on standard | ISO 15407-2 |
| Mounting position | Any |
| Symbol | 00991467 |
| Operating pressure | 1 MPa |
| Operating pressure | 10 bar |
| CE mark (see declaration of conformity) | To EU Low Voltage Directive |
| UKCA marking (see declaration of conformity) | To UK regulations for electrical equipment |
| Operating medium | Compressed air to ISO 8573-1:2010 [7:4:4] |
| Note on operating and pilot medium | Lubricated operation possible (in which case lubricated operation will always be required) |
| Corrosion resistance class CRC | 0 - No corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Degree of protection | IP65 NEMA 4 |
| Pilot medium | Compressed air to ISO 8573-1:2010 [7:4:4] |
| Ambient temperature | -5 °C ... 50 °C |
| Product weight | 228 g |
| Mounting with vertical stacking | On manifold sub-base On individual sub-base |
| Material housing | Die-cast aluminium |