


# Branching module FRM-Y-D-MINI

Part number: 542184

FESTO

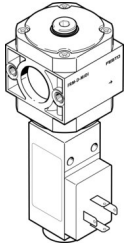

 General operating condition

## Data sheet

Feature	Value
Mounting position	Any
Design	Branching module
Symbol	00991510
Operating pressure	0 MPa ... 1.2 MPa
Operating pressure	0 bar ... 12 bar
Standard nominal flow rate in main flow direction 1->2	3300 l/min
Operational voltage range DC	0 V ... 125 V
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-] Inert gas
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-10 °C ... 60 °C
Air purity class at output	Compressed air to ISO 8573-1:2010 [7:-:-] Inert gas
Media temperature	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	507 g
Pneumatic connection, port 3	G1/4
Pneumatic connection, port 4	G1/4
Note on materials	RoHS compliant
Material housing	Die-cast aluminium