



Vacuum security valve ISV-M4

Part number: 545996

FESTO

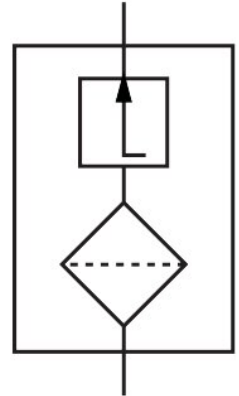

 General operating condition

Data sheet

Feature	Value
Size	M4
Suitable for ejector pulse	≤ 0.8 MPa
Suitable for ejector pulse	≤ 8 bar
Mounting position	optional
Symbol	00991481
Operating pressure	-0.095 MPa ... 0 MPa
Operating pressure	-0.95 bar ... 0 bar
Required suction volumetric flow at -0.05 MPa (-0.5 bar, -7.25 psi)	1 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Product weight	1.5 g
Type of mounting	Screw-in
Pneumatic connection, port 1	M4
Pneumatic connection, port 2	M4
Material filter	Sintered bronze
Material housing	Wrought aluminium alloy