


Plug socket with cable KMEB-3-24-5-LED

Part number: 547269

FESTO

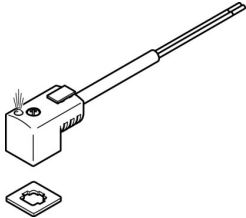

 General operating condition

Data sheet

| Feature | Value |
|------------------------------------------------------|------------------------------------------|
| Signal status display | Yellow LED |
| Mounting position | optional |
| Product weight | 230 g |
| Electrical connection 1 | Socket, to EN 175301-803, type C |
| Electrical connection 1, design | Angular |
| Electrical connection 1, connection type | Socket |
| Electrical connection 1, cable outlet | Angled |
| Electrical connection 1, note on cable outlet | 90° |
| Electrical connection 1, number of connections/cores | 2 |
| Electrical connection 1, type of mounting | On solenoid valve via M2.5 central screw |
| Electrical connection 2, connector system | Open end |
| Electrical connection 2, number of connections/cores | 2 |
| Nominal operating voltage DC | 24 V |
| Reverse polarity protection | For all electrical connections |
| Protective conductor connection | Not available |
| Cable length | 5 m |
| Cable characteristic | Standard |
| Cable diameter | 5.2 mm |
| Cable structure | 2 x 0.75 mm ² |
| Wire ends | Wire ferrule |
| Degree of protection | IP65 To IEC 60529 |
| Ambient temperature | -20 °C ... 80 °C |
| CE mark (see declaration of conformity) | In accordance with EU RoHS Directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Pollution degree | 3 |
| Corrosion resistance class CRC | 1 - Low corrosion stress |
| Material cable sheath | PVC |
| Material housing | PC |
| Material seals | NBR |
| Material electrical contact | Silver-plated copper alloy |