


# Axial kit EAMM-A-D32-57A

Part number: 550980

FESTO

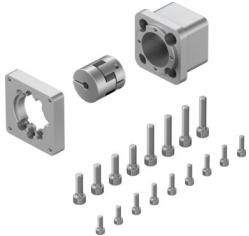

 [General operating condition](#)

## Data sheet

| Feature                  | Value                  |
|--------------------------|------------------------|
| Nominal length           | 50.5 mm                |
| Mounting position        | optional               |
| Max. rotational speed    | 8000 rpm               |
| LABS (PWIS) conformity   | VDMA24364-B2-L         |
| Storage temperature      | -25 °C ... 60 °C       |
| Relative air humidity    | 0 - 95%                |
| Degree of protection     | IP40                   |
| Ambient temperature      | -10 °C ... 60 °C       |
| Mass moment of inertia   | 5.87 kgmm <sup>2</sup> |
| Transmittable torque     | 6.5 Nm                 |
| Product weight           | 270 g                  |
| Interface code, actuator | D32<br>D32C            |
| Interface code, motor in | 57A                    |
| Note on materials        | RoHS-compliant         |