


# Fibre-optic cable SOOC-TB-F-M4-2-R2

Part number: 552818

FESTO

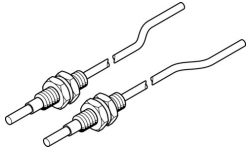

 General operating condition

## Data sheet

Feature	Value
Note on materials	RoHS compliant
Measurement method	Through-beam sensor
Min. object diameter	0.15 mm
Fibre-optic - special feature	Flexible
Operating distance	300 mm
Ambient temperature	-40 °C ... 70 °C
Head size	M4
Fibre-optic length	2 m
Min. bending radius	2 mm
Max. tightening torque	2 Nm
Outside diameter	2.2 mm
Material housing	Brass, nickel-plated
Material fibre-optic	Packaging unit
Degree of protection	IP66
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III