


Distributor block MS6N-FRM-FRZ

Part number: 554102

FESTO

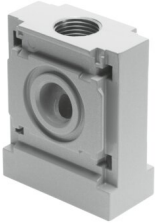

 General operating condition

Data sheet

Feature	Value
Mounting position	optional
Design	Branching module
Symbol	00991510
Operating pressure	0 bar ... 20 bar
Standard nominal flow rate in main flow direction 1->2	14600 l/min
Standard nominal flow rate, outlet upwards	10400 l/min
Standard nominal flow rate, outlet downwards	9850 l/min
Approval	c UL us - Recognized (OL)
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4] Inert gas
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-10 °C ... 60 °C
Media temperature	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	163 g
Pneumatic connection, port 3	NPT1/2-14
Pneumatic connection, port 4	NPT1/2-14
Note on materials	RoHS-compliant
Material housing	Die-cast aluminium