


Clevis foot LSN-40

Part number: 5562

FESTO

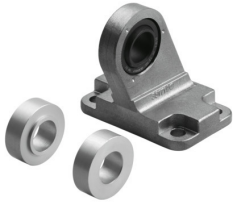

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------------|-------------------------------|
| Size | 40 |
| Corrosion resistance class CRC | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Ambient temperature | -40 °C ... 120 °C |
| Max. load capacity | 1.5 kN |
| Product weight | 219 g |
| Note on materials | RoHS-compliant |
| Material mounting | High-alloy steel |
| Material bushing | Wrought aluminium alloy |
| Material rod end bearing | Steel PTFE |