


# Manifold sub-base VABV-S6-1Q-N12

Part number: 556988

FESTO

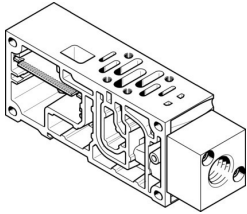

 [General operating condition](#)

## Data sheet

Feature	Value
Construction width	43 mm
Vibration resistance	Transport application test with severity level 2 to FN 942017-4 and EN 60068-2-6
Shock resistance	Shock test with severity level 2 to FN 942017-5 and EN 60068-2-27
Note on forced dynamization	Switching frequency min. 1/month
CE mark (see declaration of conformity)	To EU Low Voltage Directive
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	570 g
Pneumatic connection, port 1	1/2 NPT
Note on materials	RoHS-compliant
Material plate	Die-cast aluminium