


Manifold rail MHJ10-P16

Part number: 557608

FESTO

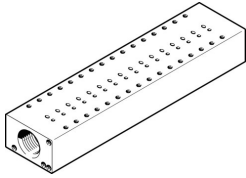

 [General operating condition](#)

Data sheet

Feature	Value
Grid dimension	11 mm
Reverse polarity protection	For operating voltage
Max. number of valve positions	16 Versions according to customer specifications possible
Approval	RCM trademark
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Product weight	635 g
Type of mounting	Via mounting bracket
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	M7
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy, anodised