


Manifold sub-base VABV-S2-2S-N12-T2

Part number: 560843

FESTO

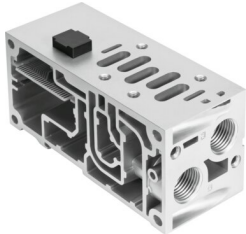

 [General operating condition](#)

Data sheet

| Feature | Value |
|--|--|
| Grid dimension | 59 mm |
| Terminal type | 44 |
| Operating pressure | -0.09 MPa ... 1 MPa |
| Operating pressure | -0.9 bar ... 10 bar |
| CE mark (see declaration of conformity) | To EU Low Voltage Directive |
| UKCA marking (see declaration of conformity) | To UK regulations for electrical equipment |
| Corrosion resistance class CRC | 0 - No corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Product weight | 610 g |
| Pneumatic connection, port 2 | 1/2 NPT |
| Pneumatic connection, port 4 | 1/2 NPT |
| Note on materials | RoHS-compliant |
| Material plate | Die-cast aluminium |