


End plate VMPAL-EPR

Part number: 560945

FESTO

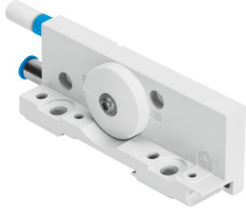

 [General operating condition](#)

Data sheet

Feature	Value
Width	24.8 mm
Length	107.3 mm
Integrated function	Pilot air selector for defining the pilot air supply (internal or external)
Valve terminal structure	Valve sizes can be mixed
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 IP67
Note on degree of protection	In mounted state
Ambient temperature	-5 °C ... 50 °C
Product weight	180 g
Pilot air port 12/14	M7
Pilot exhaust port 82/84	M7
Note on materials	RoHS compliant
Material end plate	Die-cast aluminium Reinforced PA