


# End plate VMPAL-EPR-SP

Part number: 560947

FESTO

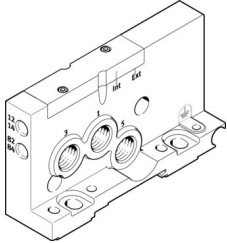

 General operating condition

## Data sheet

Feature	Value
Width	28.8 mm
Length	107.3 mm
Integrated function	Pilot air selector for defining the pilot air supply (internal or external)
Flow direction	Reversible
Valve terminal structure	Valve sizes can be mixed
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 IP67
Note on degree of protection	In assembled state
Ambient temperature	-5 °C ... 50 °C
Product weight	180 g
Pilot air port 12/14	M7
Pilot exhaust port 82/84	M7
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 3	G1/4
Pneumatic connection, port 5	G1/4
Note on materials	RoHS-compliant
Material end plate	Die-cast aluminium PA-reinforced