


# Power supply module VMPAL-SP-0

Part number: 560950

FESTO

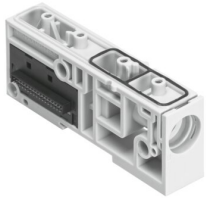

 [General operating condition](#)

## Data sheet

| Feature                        | Value                                    |
|--------------------------------|--|
| Width                          | 23.2 mm                                  |
| Length                         | 107.3 mm                                 |
| Integrated function            | With electrical interlinking module      |
| Valve terminal structure       | Valve sizes can be mixed                 |
| Operating pressure             | -0.09 MPa ... 1 MPa                      |
| Operating pressure             | -0.9 bar ... 10 bar                      |
| Pilot pressure                 | 0.3 MPa ... 0.8 MPa                      |
| Pilot pressure                 | 3 bar ... 8 bar                          |
| Corrosion resistance class CRC | 3 - high corrosion stress                |
| LABS (PWIS) conformity         | VDMA24364-B1/B2-L                        |
| Ambient temperature            | -5 °C ... 50 °C                          |
| Product weight                 | 50 g                                     |
| Pneumatic connection, port 1   | For 20 mm cartridge                      |
| Note on materials              | RoHS-compliant                           |
| Material supply module         | Wrought aluminium alloy<br>PA-reinforced |