


Electrical interlinking module VMPAL-EVAP-14-2-4

FESTO

Part number: 560970

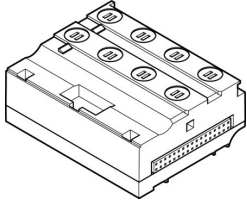

 [General operating condition](#)

Data sheet

Feature	Value
Valve size	14 mm
Max. number of valve positions	4
Max. number of valve coils	8
Integrated function	Colour-coded assignment of the valve function
Nominal operating voltage DC	24 V
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C ... 50 °C
Product weight	29 g
Housing colour	Black
Material housing	PA
Note on materials	RoHS-compliant