
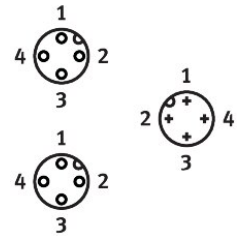



Push-in T-connector NEDU-M12D4-M12T4-IS

Part number: 562248

FESTO

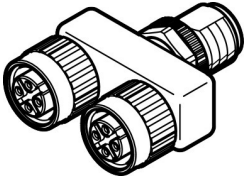

 General operating condition

Data sheet

Feature	Value
Based on standard	EN 61076-2-101
Explosion protection	The information in the certificate must be observed! Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Frequency of connection	100
Type of mounting	Screw-in
Product weight	25.5 g
Electrical connection	4-pin/4-pin/4-pin A-coded/A-coded/A-coded Socket/socket/plug connector M12x1/M12x1/M12x1
Symbol	00992230
Operational voltage range DC	0 V ... 30 V
Degree of protection	IP65 IP67
Ambient temperature	-25 °C ... 85 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class CRC	3 - high corrosion stress
Material housing	TPE-U(PU) reinforced Die-cast zinc
Material union nut	PA-reinforced
Material seals	FPM
Material electrical contact	Copper alloy Bronze