


# Throttle plate VABF-S7-F1B1P2-F

Part number: 563395

FESTO

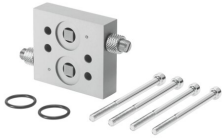

[PDF](#) General operating condition

## Data sheet

Feature	Value
Mounting position	optional
Pilot air supply	External Internal
Symbol	00991454
Operating pressure	0 MPa ... 1.2 MPa
Operating pressure	0 bar ... 12 bar
Explosion protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Corrosion resistance class CRC	4 - Very high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Degree of protection	IP65
Type of mounting	With through-hole
Pilot air port 12	G1/4
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	Flange 1/4 NAMUR port pattern
Pneumatic connection, port 3	G1/4
Note on materials	RoHS-compliant
Material sub-base	Ematal coated aluminium
Material seals	NBR