


# Push-in T-fitting QBMTL-10-32-UNF-5/32-U

Part number: 572296

FESTO

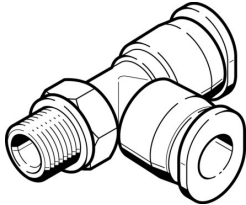

 General operating condition

## Data sheet

Feature	Value
Size	Mini
Nominal size	2.489 mm
Type of seal on screwed plug	Sealing ring
Mounting position	optional
Design	T-shape, additional push-in connector, lengthwise
Size of pack	10
Design	Push-pull principle
Operating pressure complete temperature range	-0.095 MPa ... 1 MPa
Operating pressure complete temperature range	-0.95 bar ... 10 bar
Operating pressure complete temperature range	-13.775 psi ... 145 psi
Operating medium	Compressed air to ISO 8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	0 °C ... 60 °C
Max. tightening torque	1.5 Nm
Product weight	4.99 g
Type of mounting	External hex 5/16
Pneumatic connection, port 1	Male thread 10-32 UNF-2A
Pneumatic connection, port 2	For tubing outside diameter of 5/32"
Ambient temperature	32 °F ... 140 °F
Colour of release ring	grey
Note on materials	RoHS-compliant
Material housing	PBT
Material release ring	POM
Material tubing seal	NBR
Material tubing clamp component	High-alloy stainless steel