


# Adapter VMPAL-F10-M7

Part number: 572380

FESTO

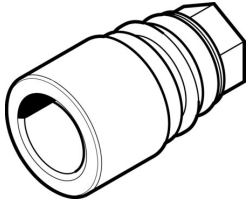

 [General operating condition](#)

## Data sheet

| Feature                        | Value                         |
|--------------------------------|-------------------------------|
| Size of pack                   | 10                            |
| Operating pressure             | -0.09 MPa ... 1 MPa           |
| Operating pressure             | -0.9 bar ... 10 bar           |
| Operating pressure             | -13.05 psi ... 145 psi        |
| Corrosion resistance class CRC | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity         | VDMA24364-B1/B2-L             |
| Ambient temperature            | -5 °C ... 50 °C               |
| Product weight                 | 17 g                          |
| Pneumatic connection, port 1   | Cartridge 10 mm               |
| Pneumatic connection, port 2   | M7                            |
| Note on materials              | RoHS compliant                |
| Material housing               | Wrought aluminium alloy       |