


Plug NECU-S1W9-C2-ACO

Part number: 574588

FESTO

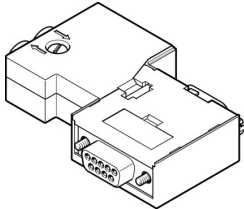

 [General operating condition](#)

Data sheet

Feature	Value
Type of mounting	4-40 UNC-2B
Product weight	59 g
Field bus interface	Sub-D, 9-pin, socket
Electrical connection 1	Socket, sub-D, 9-pin
Electrical connection 2	Screw terminal, can be screened
Baud rate	1 Mbps
Permissible cable diameter	8 mm
Permissible cable diameter	8 mm
Connection cross section	0.14 mm ² ... 0.5 mm ²
Degree of protection	IP20
Ambient temperature	-20 °C ... 70 °C
Relative air humidity	75% at 25°C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class CRC	1 - Low corrosion stress
Material housing	PC-reinforced