


# Terminal strip NECU-L3G7-C1

Part number: 576319

FESTO

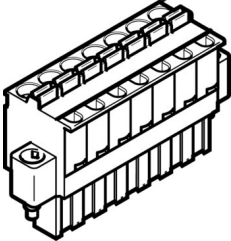

 General operating condition

## Data sheet

Feature	Value
Approval	c UL us listed (OL)
Frequency of connection	100
Mounting position	optional
Product weight	12.8 g
Electrical connection	7-pin Spring-loaded terminal Straight plug
Operational voltage range DC	0 V ... 30 V
Current rating at 40° C	12 A
Immunity to surge	4 kV
Connection cross section	0.2 mm <sup>2</sup> ... 2.5 mm <sup>2</sup>
Ambient temperature	-40 °C ... 85 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Pollution degree	3
Corrosion resistance class CRC	2 - Moderate corrosion stress
Material housing	PA
Housing colour	Black
Material electrical contact	Copper alloy Tin-plated