


# Common supply manifold VABM-B10-20-G38-3-P53-E

Part number: 576415

FESTO

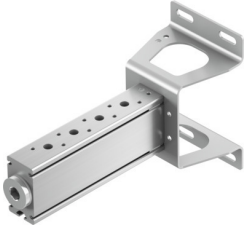

 [General operating condition](#)

## Data sheet

Feature	Value
Grid dimension	22 mm
Mounting position	optional
Max. number of valve positions	3
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	282 g
Type of mounting	Via mounting bracket
Pneumatic connection, port 1	G3/8
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy