


Sub-base VMPAC-AP-14-SP-1

Part number: 576576

FESTO

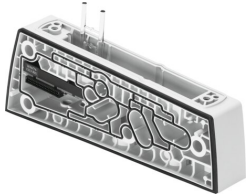

 [General operating condition](#)

Data sheet

Feature	Value
Width	32.8 mm
Length	169 mm
Grid dimension	26.8 mm
Max. number of valve positions	1
Operating pressure	-0.9 bar ... 8 bar
Pilot pressure	3 bar ... 8 bar
Corrosion resistance class CRC	4 - Very high corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-5 °C ... 50 °C
Product weight	160 g
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	G1/4
Pneumatic connection, port 3	G1/4
Pneumatic connection, port 4	G1/4
Pneumatic connection, port 5	G1/4
Note on materials	RoHS-compliant
Material housing	PA-reinforced