


Elbow quick connector LCK-1/4-PK-6-KU

Part number: 6262

FESTO

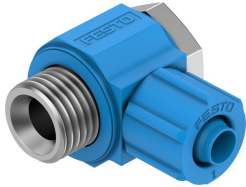

 [General operating condition](#)

Data sheet

Feature	Value
Nominal size	5.3 mm
Type of seal on screwed plug	Sealing edge
Mounting position	optional
Design	L-shape
Size of pack	10
Operating pressure complete temperature range	-0.095 MPa ... 1 MPa
Operating pressure complete temperature range	-0.95 bar ... 10 bar
Operating pressure complete temperature range	-13.775 psi ... 145 psi
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Pneumatic connection, port 1	Male thread G1/4
Pneumatic connection, port 2	For tubing outside diameter of 8 mm For barbed fitting inside diameter of 6 mm with nut
Material union nut	POM
Note on materials	RoHS-compliant
Material hollow bolt	Wrought aluminium alloy, anodised
Material swivel fitting	POM