


# Common supply manifold VABM-B10-25-N12-6-P53

Part number: 8026232

FESTO

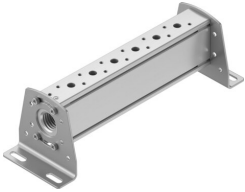

 [General operating condition](#)

## Data sheet

Feature	Value
Grid dimension	27.5 mm
Mounting position	optional
Max. number of valve positions	6
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	586 g
Type of mounting	Via mounting bracket
Pneumatic connection, port 1	1/2 NPT
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy