


# Axial kit EAMM-A-L38-57AA

Part number: 8063457

FESTO

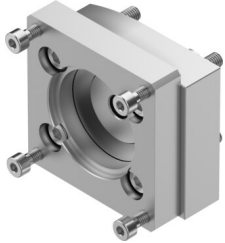

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	26.9 mm
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	3.2 kgmm <sup>2</sup>
Transmittable torque	4.4 Nm
Product weight	281 g
Interface code, actuator	L38
Interface code, motor in	57AA
Note on materials	RoHS-compliant